
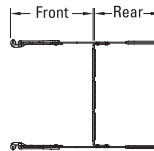


Product Cut Sheet

CCS COMBINATION CABLING SECTION

The CCS Combination Cabling Section offers the best of CPI's cabling sections, but with added design features. This cabling section is double-sided with the front side featuring plastic cable guides (like those used on the MCS Master Cabling Section,) while the back retains the classic VCS Vertical Cabling Section design.

- 1U cable guides on the front designed for fanning and managing patch cords
- Open cabling section on the rear provides easy access and routes cable bundles feeding into the back of patch panels
- Edge-protected pass through ports make it easy to route cable from front to back; vertical slots along the center separator secure cable bundles neatly with optional Saf-T-Grip® Cable Management Straps
- Plastic Cable Guides meet UL 94V-0 Flame Resistant standards
- Innovative SwitchGate Door/Cover (front) is easily opened from the right or left and can be removed so that cable does not have to thread through guides
- Attach to Standard Racks, Universal Racks, QuadraRack or Adjustable QuadraRack frames
- Mounting hardware and doors are included

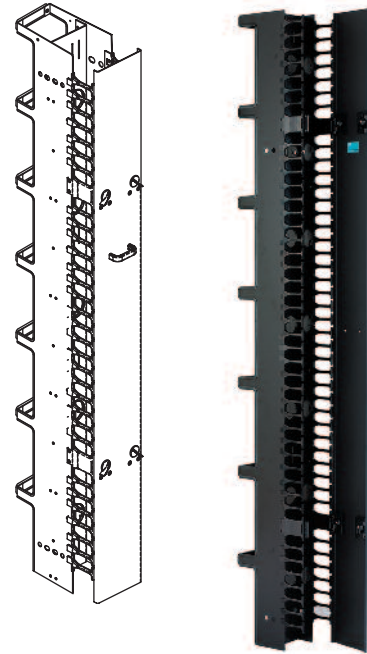

Usable Depth
 For 3"D (80 mm) Rack Version:
 Front=5.90" (149.9 mm); Rear=5.35" (135.9 mm)
 For 6"D (150 mm) Rack Version:
 Front=7.40" (188.0 mm); Rear=6.85" (174.0 mm)

Part Number 3"D (80 mm) Racks	Height ft (m)	Depth in (mm)	Shipping Weight lb (kg)
3.65"W (92.7 mm)			
30161-X01	6 (1.8)	12.24 (311)	25 (11.3)
30161-X03	7 (2.1)	12.24 (311)	29 (13.2)
30161-X05	7.6 (2.3)	12.24 (311)	31 (14.1)
30161-X15	8 (2.4)	12.24 (311)	33 (15.0)
30161-X08	9 (2.7)	12.24 (311)	38 (17.2)
6"W (150 mm)			
30162-X01	6 (1.8)	12.24 (311)	29 (13.2)
30162-X03	7 (2.1)	12.24 (311)	34 (15.4)
30162-X05	7.6 (2.3)	12.24 (311)	37 (16.8)
30162-X15	8 (2.4)	12.24 (311)	39 (17.7)
30162-X08	9 (2.7)	12.24 (311)	44 (20.0)
10"W (250 mm)			
30163-X01	6 (1.8)	12.24 (311)	40 (18.1)
30163-X03	7 (2.1)	12.24 (311)	46 (20.9)
30163-X05	7.6 (2.3)	12.24 (311)	50 (22.7)
30163-X15	8 (2.4)	12.24 (311)	53 (24.0)
30163-X08	9 (2.7)	12.24 (311)	59 (26.8)

X=Color; 7=Black, E=Glacier White.

Part Number 6"D (150 mm) Racks	Height ft (m)	Depth in (mm)	Shipping Weight lb (kg)
3.65"W (92.7 mm)			
30164-X01	6 (1.8)	14.61 (371)	28 (12.7)
30164-X03	7 (2.1)	14.61 (371)	33 (15.0)
30164-X05	7.6 (2.3)	14.61 (371)	36 (16.3)
30164-X15	8 (2.4)	14.61 (371)	38 (17.2)
30164-X08	9 (2.7)	14.61 (371)	43 (19.5)
6"W (150 mm)			
30165-X01	6 (1.8)	14.61 (371)	33 (15.0)
30165-X03	7 (2.1)	14.61 (371)	38 (17.2)
30165-X05	7.6 (2.3)	14.61 (371)	41 (18.6)
30165-X15	8 (2.4)	14.61 (371)	44 (20.0)
30165-X08	9 (2.7)	14.61 (371)	49 (22.2)
10"W (250 mm)			
30166-X01	6 (1.8)	14.61 (371)	42 (19.1)
30166-X03	7 (2.1)	14.61 (371)	49 (22.2)
30166-X05	7.6 (2.3)	14.61 (371)	53 (24.0)
30166-X15	8 (2.4)	14.61 (371)	56 (25.4)
30166-X08	9 (2.7)	14.61 (371)	63 (28.6)

800-834-4969 in US & Canada • www.chatsworth.com



CHATSWORTH PRODUCTS

©2013 Chatsworth Products, Inc. All rights reserved. CPI, CPI Passive Cooling, GlobalFrame, MegaFrame, Saf-T-Grip, Seismic Frame, SlimFrame, TeraFrame, Cube-iT Plus, Evolution, OnTrac, Velocity and QuadraRack are federally registered trademarks of Chatsworth Products. eConnect and Simply Efficient are trademarks of Chatsworth Products. All other trademarks belong to their respective companies. Rev.3 07/13