


Product Cut Sheet

GLOBAL VERTICAL CABLING SECTION

The Global Vertical Cabling Section is an adaptable vertical cable management solution with a unique, two-piece design that reduces shipping size and cost. The two parts can be quickly assembled and then bolted to CPI's Universal and Standard racks, as well as QuadraRack and Adjustable QuadraRack frames. It ships partially assembled with patented cable guide fingers at 1U intervals. Each single-sided section includes a two-piece section, a two-piece door/cover and mounting hardware. Each double-sided section is a one-piece section and two-piece door/cover.

- Patented cable guide fingers at 1U intervals provide an organized pathway for cable and patch cords
- 7'H (2.1 m) provides 45U
- Snap-on, hinged door/cover hides cable for a finished appearance, yet allows quick access to cable for making changes
- Door/cover swings on hinges to open left or right
- Acorn nuts eliminate sharp edges, reducing injuries and torn cables
- Seven 2.5" (64 mm) pass-through ports allow cables to transition from front to back

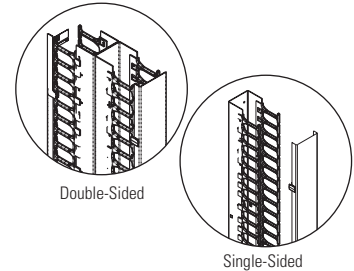

Additional cable management can be achieved by placing sections back-to-back.

Cable Rings For GVCS

Use rings to create a separate cable path on back of Global Vertical Cabling Section to organize wires for a neat, professional installation. Contains seven rings.

Part Number & Finish		Description	Shipping Weight lb (kg)
Black	Glacier White		
12836-701	12836-E01	3.65"W (92.7 mm) Rings	4 (1.8)
12836-702	12836-E02	6"W (150 mm) Rings	5 (2.3)
12836-703	12836-E03	10"W (250 mm) Rings	5 (2.3)



Rings shown attached to GVCS

Part Number	Description	Shipping Weight lb (kg)
Single-Sided GVCS		
12830-X03	7'H x 3.65"W x 6.76"D, Narrow (2.1 m x 92.7 mm x 171.7 mm)	16 (7.3)
12832-X03	7'H x 3.65"W x 9.30"D, Narrow (2.1 m x 92.7 mm x 236.2 mm)	18 (8.2)
12831-X03	7'H x 6"W x 6.76"D, Wide (2.1 m x 150 mm x 171.7 mm)	19 (8.6)
12833-X03	7'H x 6"W x 9.30"D, Wide (2.1 m x 150 mm x 236.2 mm)	22 (10.0)
12834-X03	7'H x 10"W x 6.76"D, Wide (2.1 m x 250 mm x 171.7 mm)	26 (11.8)
12835-X03	7'H x 10"W x 9.30"D, Wide (2.1 m x 250 mm x 236.2 mm)	28 (12.7)
Double-Sided GVCS		
14830-X03	7'H x 3.65"W x 13.52"D, Narrow (2.1 m x 92.7 mm x 343.4 mm)	32 (14.5)
14831-X03	7'H x 6"W x 13.52"D, Wide (2.1 m x 150 mm x 343.4 mm)	39 (17.7)
14832-X03	7'H x 10"W x 13.52"D, Wide (2.1 m x 250 mm x 343.4 mm)	47 (21.3)

X=Color: 5=Clear, 7=Black, E=Glacier White. Clear (-5XX) versions are only available in Double-Sided versions, and have black doors/covers and cable guides.

800-834-4969 in U.S. & Canada • www.chatsworth.com

US & Canada

+1-800-834-4969
Toronto, Ontario, Canada
+905-850-7770
chatsworth.com

Latin America

+52-55-5203-7525
Toll Free within Mexico
01-800-01-7592
chatsworth.com.co

Europe

+44-1628-524-834
chatsworthproducts.co.uk

Middle East & Africa

Dubai, UAE
+971-4-2602125
chatsworthproducts.co.uk

Asia Pacific

+86 21 6880-0266
chatsworth.com.cn

techsupport@chatsworth.com



CHATSWORTH
PRODUCTS